


3050 Spruce Street, Saint Louis, MO 63103, USA

Website: www.sigmaaldrich.comEmail USA: techserv@sial.comOutside USA: eurtechserv@sial.com

Product Specification

Product Name:
Cyclophosphamide monohydrate - ISOPAC®

Product Number: **C7397**
 CAS Number: 6055-19-2
 MDL: MFCD00149395
 Formula: $C_7H_{15}Cl_2N_2O_2P \cdot H_2O$
 Formula Weight: 279.1 g/mol
 Storage Temperature: 2 - 8 °C

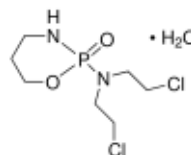

TEST

Specification

Appearance (Color)	White to Off-White
Appearance (Form)	Powder
Proton NMR spectrum	Conforms to Structure
Water (by Karl Fischer)	4.7 - 7.8 %
Solubility (Color)	Colorless
Solubility (Turbidity)	Clear
100 mg/ml in H ₂ O	
Purity (HPLC)	97.0 - 103.0 %
Anhydrous Basis	
Recommended Retest Period	-----
3 Years	

Specification: PRD.0.ZQ5.10000103020

Sigma-Aldrich warrants, that at the time of the quality release or subsequent retest date this product conformed to the information contained in this publication. The current Specification sheet may be available at Sigma-Aldrich.com. For further inquiries, please contact Technical Service. Purchaser must determine the suitability of the product for its particular use. See reverse side of invoice or packing slip for additional terms and conditions of sale.

